


空气挡板, 前面板, 经过升级获得更高电磁屏蔽性, 碳钢

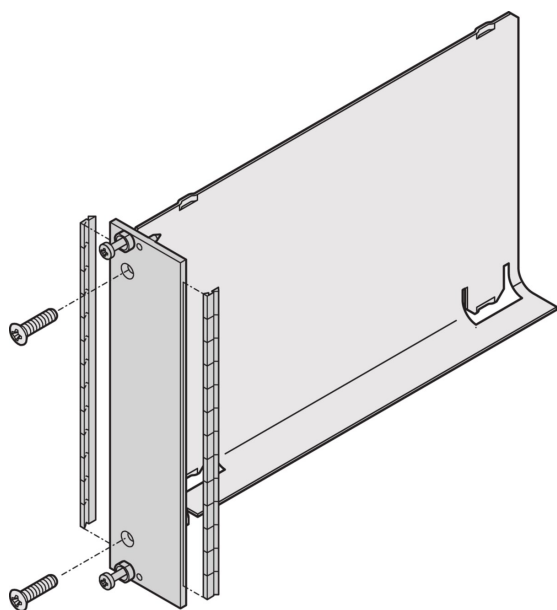

带扁平前面板的空气挡板可以覆盖空插槽, 防止空气向外泄漏。扁平前面板可以采用不锈钢 EMC 垫片。

功能

空气挡板可避免空插槽空气向外泄漏

安装方式, 按压上盖推入到导轨中

产品类型: 空气挡板
材料: 铝
完成: 阳极氧化; 钝化
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac
类型: 带前面板



技术参数

物料号	机架高度	包装数量	深度	EMC 屏蔽	机架宽度	搭配
20848-712	3U	1	160mm	无 (可改装)	4HP	插箱, 仪器箱
20848-721	6U	1	220mm	无 (可改装)	4HP	插箱, 仪器箱
20848-720	6U	1	160mm	无 (可改装)	4HP	插箱, 仪器箱
20848-713	3U	1	220mm	无 (可改装)	4HP	插箱, 仪器箱

其他产品详情

可应要求提供适用 280 mm 深度和 80 mm 后部 I/O 板的空气挡板。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE