


卡笼，可沿水平方向安装板卡

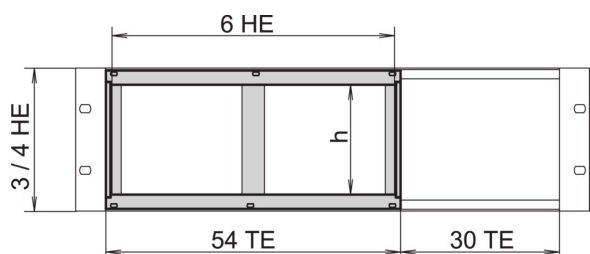

板笼为水平板卡提供了安装选项，便于6U板卡插在3U或4U高的插箱或者桌面仪器箱。请单独订购前面板，以组成装配套件。

功能

适用在 3 或 4 U高插箱/机箱中水平安装双排欧卡电路板

产品系列: EuropacPRO

产品类型: 安装套件

搭配: 插箱



技术参数

物料号	机架高度	机架宽度	包装数量	材料	类型
24564-117	3U	20HP	1	铝, 锌合金	水平板安装
24564-118	3U	20HP	1	铝, 锌合金	水平板安装, 带有长唇
24564-217	4U	28HP	1	铝, 锌合金	水平板安装

其他产品详情

请单独订购前框架和 EMC 屏蔽材料。

需要 54 TE 空间。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE