


M2.5 螺钉套，镀镍黄铜；100 个

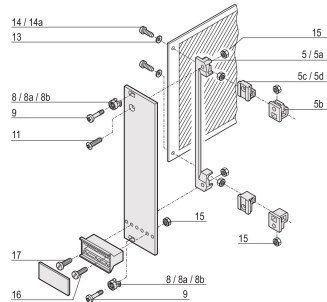

物料号




21100-660

紧固前面板时，螺钉套可用于引导固定螺钉。

功能

紧固前面板时，螺钉套可用于螺钉安装导向定位

螺钉套装在前面板上的长圆孔中

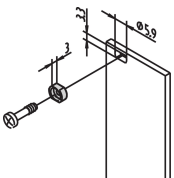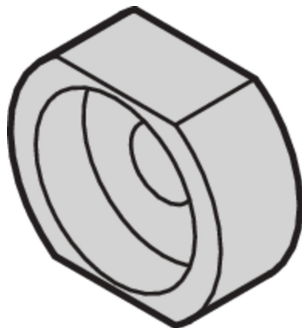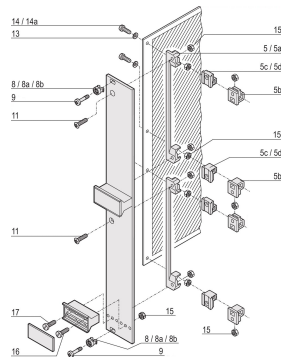

产品属性

材料: 黄铜

完成: 镀镍

包装数量: 100

深度 (D): 4.4mm

高度 (H): 6mm

产品类型: 套管

宽度 (W): 8mm

搭配: 前面板

净重: 0.078kg


*所示价格为每件价格, 不含增值税。是否含包装费和运费取决于当地情况。如果这些费用应为总价的一部分, 报价中将包含包装费和运费。给定的价格为非约束性建议零售价 (RRP), 即 nVent 标价。当地经销商的最终销售价格可能会有所不同。在 SCHROFF.nVent.com 上请求或生成的报价仅对商业客户 (B2B) 有效。上面显示的交货时间是从 nVent SCHROFF 工厂发货该项目的估计值。运输时间不包括在此估计中, 因为运输时间可能会有所不同, 具体取决于送货地址、包裹尺寸和其他因素。对于配置的产品, 在非推荐区域 (“检测到的碰撞区域”) 进行的开孔和修改可能会产生额外的工程和/或设计成本, 这可能会增加最初的报价。

其他产品详情

金属螺钉套, 必须压入面板中

所有套管都可以用于 >2 HP 的前面板。

图

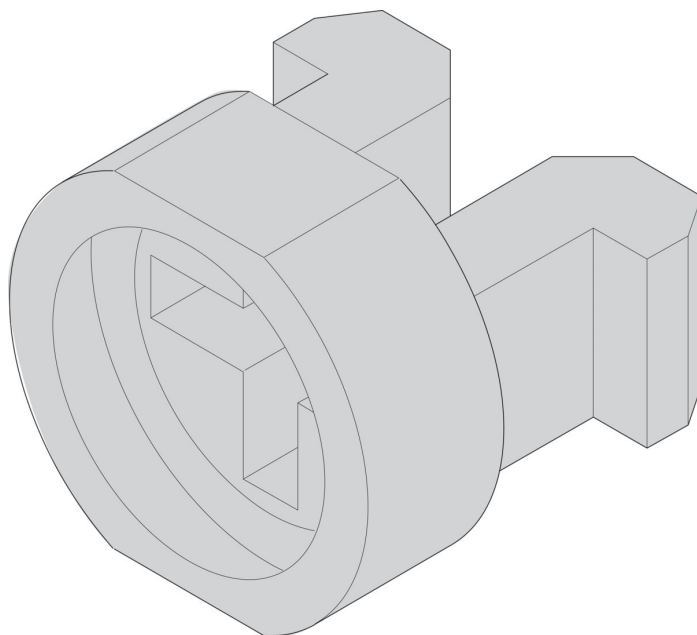

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE