


导轨，带适于 CompactPCI/ VME64x 的编码，偏移 0.1 英寸，PC，160 mm，槽宽 2 mm，10 个

物料号

24568-359

New generation of Wih Coding, Offset type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

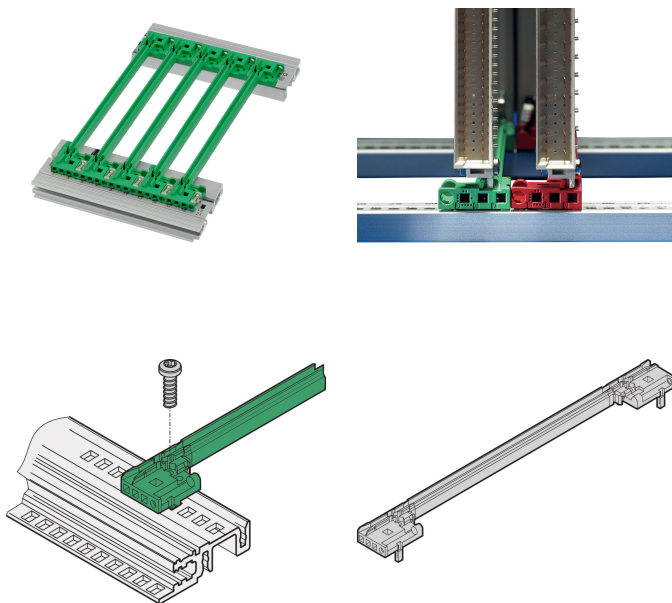

功能

新一代编码型，偏置型塑料导轨，实现 PCB 或插入式装置的可靠固定

稳定性显著提高，得益于优化设计和高质量材料 (PC)

提高防火安全性能，符合 EN 45545-2 规范 R22, R23 和 R24 中的最高危险等级 HL3

“无卤素”，符合 IEC 61249-2-21 标准

导轨可以卡入水平横梁（铝挤压件）或 1.5 mm 厚板中

可以通过螺栓固定到 H 型和 R 型水平横梁，以满足更高的抗冲击和振动要求

可选 ESD 夹，用于 PCB 和水平横梁之间的导电触点

存储温度：从 -40 °C.. 130 °C

产品属性

包装数量: 10
板深度: 160mm
槽宽: 2
颜色: 绿色
符合: EN 45545-2
材料: 纤维增强型塑料
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
产品类型: 导轨
类型: 编码, 偏移
搭配: 插箱; 仪器箱; 19" 机箱; 系统
净重: 0.085kg

*所示价格为每件价格, 不含增值税。是否含包装费和运费取决于当地情况。如果这些费用应为总价的一部分, 报价中将包含包装费和运费。给定的价格为非约束性建议零售价 (RRP), 即 nVent 标价。当地经销商的最终销售价格可能会有所不同。在 SCHROFF.nVent.com 上请求或生成的报价仅对商业客户 (B2B) 有效。上面显示的交货时间是从 nVent SCHROFF 工厂发货该项目的估计值。运输时间不包括在此估计中, 因为运输时间可能会有所不同, 具体取决于送货地址、包裹尺寸和其他因素。对于配置的产品, 在非推荐区域 (“检测到的碰撞区域”) 进行的开孔和修改可能会产生额外的工程和/或设计成本, 这可能会增加最初的报价。

其他产品详情

请注意, 交货数量会按照声明的标准包装量执行 (例如, 5 件、10 件、50 件等) 我们会将不符合规定的订购数量 (例如 2 件) 更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 销售代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America Locations 1.703.722.7661	Europe Straubenzhardt, Germany +49.7082.754.0	Asia Shanghai, China +86.21.2412.6943	Middle East & India Dubai, United Arab Emirates +971.4.378.1700
Chat with us: nvent.com/schroff	Betschdorf, France +33.3.88.90.64.90	Qingdao, China +86.532.8771.6101	Bangalore, India +91.80.6715.2001
	Warsaw, Poland +48.22.209.98.35	Singapore +65.6768.5800	Istanbul, Turkey +90.216.250.7374
	Assago, Italy +39.02.932.7141	Shin-Yokohama, Japan +81.45.476.0271	Chat with us: nvent.com/schroff
	Chat with us: nvent.com/schroff	Chat with us: nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE