

CPCI PlusIO 系统，带可插拔 PSU，4 U，8 个插槽

物料号

24579-400

4 U CompactPCI PlusIO 系统，带垂直卡笼，适用一个 CPCI PlusIO 系统控制器、4 个 CompactPCI 和 3 个 CompactPCI Serial 外设板和一个 CompactPCI 3 U 可插拔电源。

功能

符合 IEC 60297 - 3 - 101、- 102、- 103 标准以及 IEEE 1101.1, 1101.10/11 标准；背板符合 PICMG 2.0 修订版 3.0 和 PICMG 2.30 修订版 1.0 标准


系统含垂直卡槽。前插板卡：3 U，160 mm 深，8 槽；后部 I/O：3 U，80 mm 深，3 槽

4 槽位背板，3 U，32 位，CompactPCI；4 槽，3 U，CompactPCI PlusIO

通过 1 U 热插拔风扇单元散热，风道从下往上

19" 兼容 PSU，250 W，3 U，8 HP

可安装硬盘

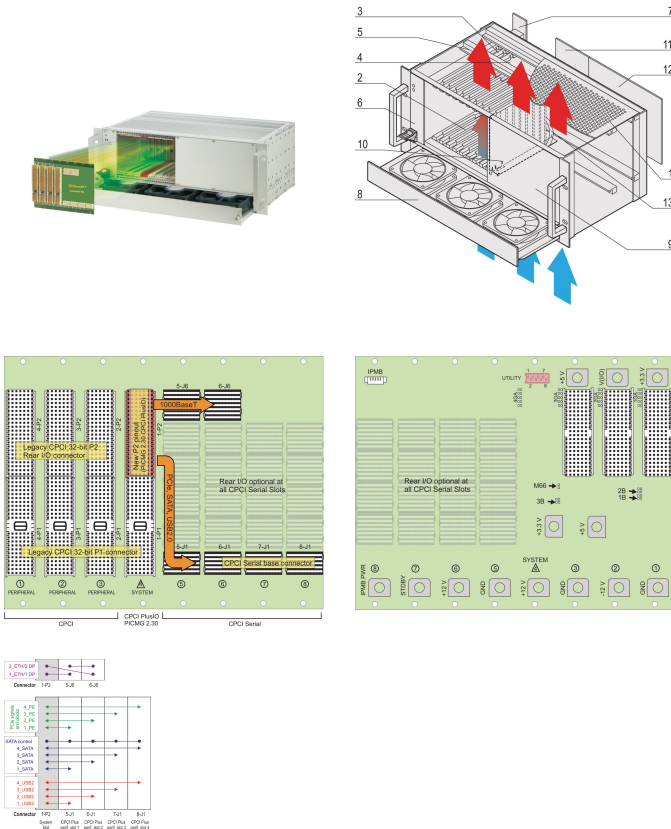

产品属性

产品类型: 系统

插槽数: 8

类型: 19" 机架安装

背板类型: 3 U，4 槽 CompactPCI 和 4 槽 CompactPCI Serial



每插槽的功率: 40W

气流方向: 从下至上

电源类型: (1) 可插拔 PSU

包含电源: 是

后部 I/O: 是

符合: PICMG 2.30 R1.0

深度: 275mm

高度: 177mm

净重: 10.8kg

包装数量: 1

[其他产品详情](#)

可应要求提供定制系统。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

按照代表索取。错误安装、使用不当或未能完全遵守 nVent Asia Middle East & India 的说明书警告，可能会造成产品故障、财产损失、严重的人身伤害或死亡，或使得保修服务无效。Dubai, United Arab

+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE