


# 导轨，带 CompactPCI/VME64x 的编码，偏移 0.1"，PC，160 mm，槽宽 2 mm

## 物料号

**64568-071**

New generation of Wih Coding, Offset type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

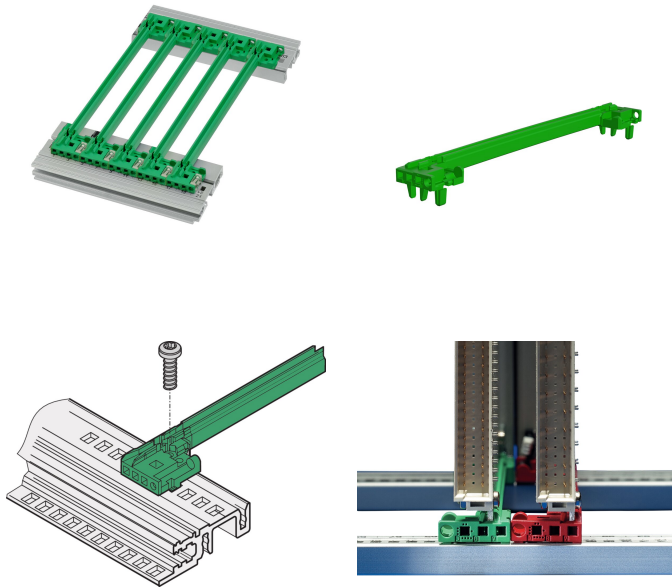

## 功能

新一代编码型, 偏置型塑料导轨, 实现 PCB 或插入式装置的可靠固定

稳定性显著提高, 得益于优化设计和高质量材料 (PC)

提高防火安全性能, 符合 EN 45545-2 规范 R22, R23 和 R24 中的最高危险等级 HL3

“无卤素”, 符合 IEC 61249-2-21 标准

导轨可以卡入水平横梁 (铝挤压件) 或 1.5 mm 厚板中

可以通过螺栓固定到 H 型和 R 型水平横梁, 以满足更高的抗冲击和振动要求

可选 ESD 夹, 用于 PCB 和水平横梁之间的导电触点

存储温度: 从 -40 °C.. 130 °C

产品属性

|                                                                                          |
|------------------------------------------------------------------------------------------|
| 包装数量: 1                                                                                  |
| 板深度: 160mm                                                                               |
| 槽宽: 2                                                                                    |
| 颜色: 绿色                                                                                   |
| 符合: EN 45545-2                                                                           |
| 材料: 纤维增强型塑料                                                                              |
| 产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac |
| 产品类型: 导轨                                                                                 |
| 类型: 编码, 偏移                                                                               |
| 搭配: 插箱; 仪器箱; 19" 机箱; 系统                                                                  |
| 毛重: 0.008kg                                                                              |

\*所示价格为每件价格, 不含增值税。是否含包装费和运费取决于当地情况。如果这些费用应为总价的一部分, 报价中将包含包装费和运费。给定的价格为非约束性建议零售价 (RRP), 即 nVent 标价。当地经销商的最终销售价格可能会有所不同。在 SCHROFF.nVent.com 上请求或生成的报价仅对商业客户 (B2B) 有效。上面显示的交货时间是从 nVent SCHROFF 工厂发货该项目的估计值。运输时间不包括在此估计中, 因为运输时间可能会有所不同, 具体取决于送货地址、包裹尺寸和其他因素。对于配置的产品, 在非推荐区域 (“检测到的碰撞区域”) 进行的开孔和修改可能会产生额外的工程和/或设计成本, 这可能会增加最初的报价。

其他产品详情

请注意, 交货数量会按照声明的标准包装量执行 (例如, 5 件、10 件、50 件等) 我们会将不符合规定的订购数量 (例如 2 件) 更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书, 或者向您的 nVent 销售代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

|                                              |                                                     |                                             |                                                                        |
|----------------------------------------------|-----------------------------------------------------|---------------------------------------------|------------------------------------------------------------------------|
| North America<br>Locations<br>1.703.722.7661 | Europe<br>Straubenzharde, Germany<br>+49.7082.754.0 | Asia<br>Shanghai, China<br>+86.21.2412.6943 | Middle East & Africa<br>Dubai, United Arab Emirates<br>+971.4.378.1700 |
| Chat with us:<br>nvent.com/schroff           | Betschdorf, France<br>+33.3.88.90.64.90             | Qingdao, China<br>+86.532.8771.6101         | Bangalore, India<br>+91.80.6715.2001                                   |
|                                              | Warsaw, Poland<br>+48.22.209.98.35                  | Singapore<br>+65.6768.5800                  | Istanbul, Turkey<br>+90.216.250.7374                                   |
|                                              | Assago, Italy<br>+39.02.932.7141                    | Shin-Yokohama, Japan<br>+81.45.476.0271     | Chat with us:<br>nvent.com/schroff                                     |
|                                              | Chat with us:<br>nvent.com/schroff                  | Chat with us:<br>nvent.com/schroff          |                                                                        |



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE