


适合用螺栓固定到侧板上的 EuropacPRO 盖板

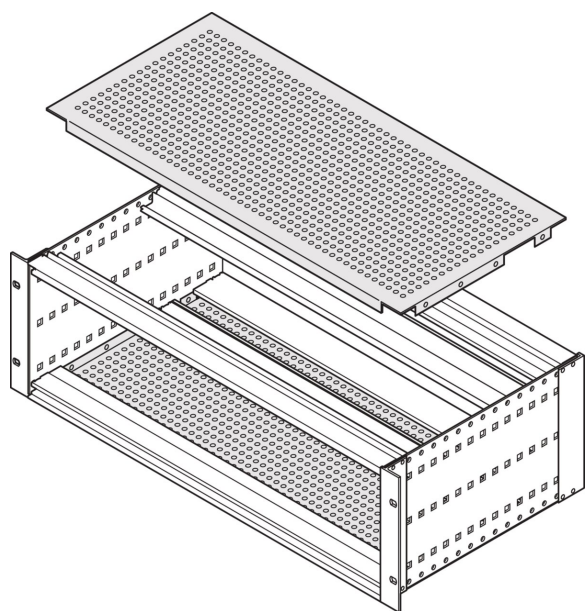

盖板用于提供电磁屏蔽或机械保护。盖板可用螺钉固定在侧面板上。

功能

适用于水平横梁的可变位置，例如标准规格的 PCB

通风率 58%

适合与所有水平导轨搭配使用

材料: 铝
产品类型: 盖板
产品系列: EuropacPRO
完成: 钝化
类型: 穿孔
搭配: 插槽



技术参数

物料号	机架宽度	深度	包装数量	包装单位	扭矩
24560-066	42HP	295mm	2	对	2.1N • m
24560-078	84HP	175mm	2	对	2.1N • m
24560-064	42HP	175mm	2	对	2.1N • m
24560-073	63HP	295mm	2	对	2.1N • m
24560-079	84HP	235mm	2	对	2.1N • m
24560-080	84HP	295mm	2	对	2.1N • m
24560-063	84HP	275mm	2	对	
24560-065	42HP	235mm	2	对	2.1N • m

物料号	机架宽度	深度	包装数量	包装单位	扭矩
24560-072	63HP	235mm	2	对	2.1N • m
24560-081	84HP	355mm	2	对	2.1N • m
24560-082	84HP	415mm	2	对	2.1N • m
24560-071	63HP	175mm	2	对	2.1N • m
24560-083	84HP	475mm	2	对	2.1N • m
24560-061	42HP	275mm	2	对	
24579-090	42HP	277.75mm	2	对	2.1N • m
24579-092	84HP	277.75mm	2	对	2.1N • m
24560-062	63HP	275mm	2	对	

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE