


带盖板时使用的 EuropacPRO 安装板

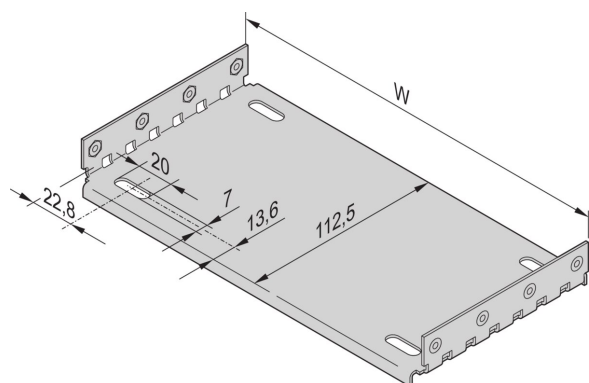

带盖板时使用的安装板，适用于安装和固定重型组件。全宽安装板（与插箱或系统机箱一样宽）可固定至侧面板。非全宽安装板可通过装配条固定至侧面板和水平横梁。

4,4”型和加强型导轨不能与安装板组合使用。适用轻型（L型）水平横梁凹槽的顶盖/底盖不能与安装板组合使用。

功能

用于安装和固定重型组件

安装板, 全宽：安装板的宽度与插箱/系统机箱一样宽，并固定在侧面板上

导轨可安装在第一和最后一个槽位置

除安装板外，还可以将 EMC 盖板安装到插箱

不能使用4.4型和“加固”型导轨

导轨可固定在首个或最后一个槽中

材料: 铝
产品系列: EuropacPRO
产品类型: 安装板
搭配: 插箱



技术参数

物料号	机架宽度	包装数量	深度	宽度	认证
34563-004	84HP	1	112.5mm	431.35mm	RoHS
34563-019	63HP	1	172.5mm	324.67mm	RoHS
34563-014	42HP	1	172.5mm	217.99mm	RoHS
34563-009	28HP	1	172.5mm	146.88mm	RoHS
34563-003	63HP	1	112.5mm	324.67mm	RoHS

物料号	机架宽度	包装数量	深度	宽度	认证
34563-002	42HP	1	112.5mm	217.99mm	RoHS
34563-001	28HP	1	112.5mm	146.88mm	RoHS
34563-024	84HP	1	172.5mm	431.35mm	RoHS
34563-044	84HP	1	412.5mm	431.35mm	
34563-042	84HP	1	352.5mm	431.35mm	
34563-028	84HP	1	292.5mm	431.35mm	
34563-026	84HP	1	232.5mm	431.35mm	

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE