


EuropacPRO Perforated Rail for Connector

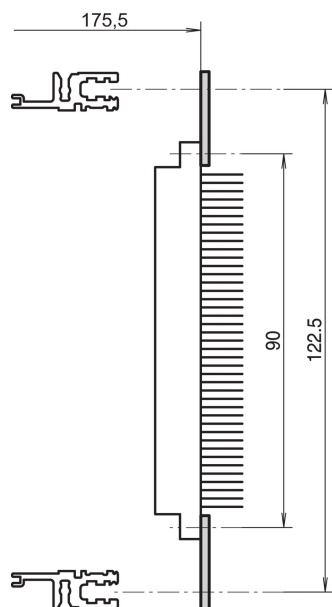

Perforated flat rail for connector mounting i.a.w. EN 60603-2 and DIN 41612, on VT horizontal rails.

功能

适配于, VT后水平横梁

适用于符合 EN 60603-2 标准的连接器安装, DIN 41612

材料: 铝
完成: 钝化
产品类型: 开孔横梁



技术参数

物料号	机架宽度	包装数量	长度	产品系列	搭配	认证
20822-052	4HP	4	20.32m m	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	插箱, 仪器箱	
20822-046	40HP	4	203.2m m	EuropacPRO	插箱	RoHS
20822-053	8HP	4	40.64m m	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	插箱, 仪器箱	
20822-051	20HP	4	101.6m m	EuropacPRO	插箱	RoHS
20822-047	60HP	4	304.8m m	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	插箱, 仪器箱	RoHS

物料号	机架宽度	包装数量	长度	产品系列	搭配	认证
20822-050	42HP	4	213.36m m	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	插箱, 仪器箱	RoHS
20822-049	28HP	4	142.24m m	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	插箱, 仪器箱	RoHS
20822-048	84HP	4	431.8m m	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO	插箱, 仪器箱	RoHS

其他产品详情

需要使用螺钉将开孔轨道固定在水平横梁上

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE