


LHX+ 空气/液体热交换器

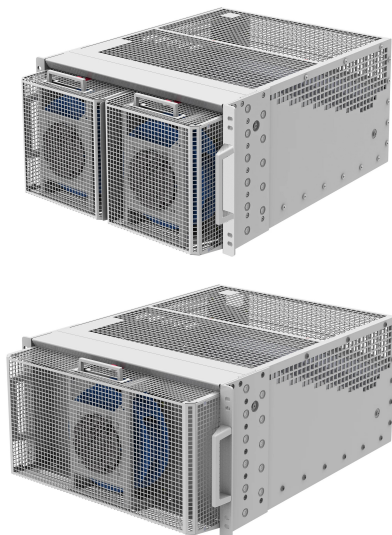

RackChiller 列间制冷空调 (IRC)

旨在为数据中心提供局部/辅助节能冷却方案。RackChiller IRC

是一款模块化、可扩展的精确冷却解决方案，可以替代或补充传统数据中心冷却基础设施。

功能

19" 可安装空气/液体热交换器，带风扇

无需拆卸热交换器即可轻松更换风扇

冷却剂从上或从下输送

深度: 500mm
产品类型: 空气/液体热交换器
气流方向: 前对顶

技术参数

Table 1/2

物料号	风扇数量	交流输入电压	包装数量	电源电压	冗余电源	冷却剂进给装置
29714-017	1	100 – 240V	1	230V min	否	底部
29714-016	2	100 – 240V	1	230V min	否	底部

Table 2/2

物料号	高度	材料	产品系列	宽度	搭配
29714-017	266mm	铝	冷却	426mm	Varistar, Varistar CP
29714-016	266mm	铝	冷却	426mm	Varistar, Varistar CP

其他产品详情

请单独订购：通过控制单元、水控制包、显示屏和门触点开关进行监控。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE