


# 电缆线

## nVent SCHROFF

电源线可以通过实际、通用的方式用可变的连接设备紧固。  
规格通用，适合不同的应用，如风扇、机柜灯、工业 PC 连接、不间断电源、系统等。

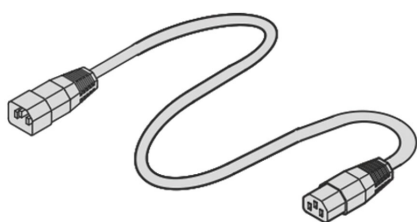

## 功能

应用：风扇, 机柜灯, 工业 PC 连接, 不间断电源和系统

产品类型: 电缆



## 技术参数

| 物料号       | 输入连接器        | 输出连接器   | 长度     | 包装数量 | 颜色 | 连接器类型 | 材料  |
|-----------|--------------|---------|--------|------|----|-------|-----|
| 62150-191 | SCHUKO / UTE | IEC C13 | 2500mm | 1    | 黑色 | 直向型   | PVC |
| 60704-020 | SCHUKO / UTE | IEC C13 | 2500mm | 1    | 灰色 | 倾斜    | PVC |
| 60103-131 | SCHUKO / UTE | IEC C13 | 2500mm | 1    | 灰色 | 直向型   | PVC |
| 60110-361 | IEC C14      | IEC C13 | 1000mm | 1    | 黑色 | 直向型   | PVC |
| 60197-053 | IEC C14      | IEC C13 | 2500mm | 1    | 黑色 | 直向型   | PVC |
| 60110-360 | IEC C14      | IEC C13 | 500mm  | 1    | 黑色 | 直向型   | PVC |
| 60103-137 | BS = 英国标准    | IEC C13 | 2500mm | 1    | 黑色 | 直向型   | PVC |
| 60103-141 | US = 美国标准    | IEC C13 | 2500mm | 1    | 黑色 | 直向型   | PVC |

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE