


用于 PMC 的插入式单元套件, 镀铬, 把手带屏蔽 (织物)

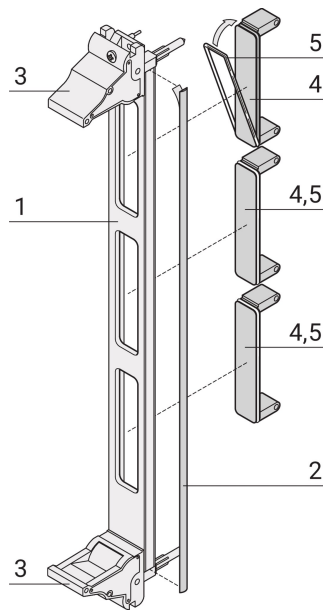

U 形前面板, 带开孔, 用于 PMC。屏蔽型, 适用于泡棉 EMC 垫片。

功能

符合 IEEE P1386, PCI 夹层卡

适用于单个 69.0 x 76.5 mm 模块或两个 139.0 x 76.5 mm 模块

适用于指定的 I/O 夹层模块 (连接到载卡)

PMC = PCI 夹层卡

FPGA = 现场可编程门阵列

U 形前面板 3 U, 4 HP, 带织物垫片

前面板的 EMC 屏蔽和前面板开孔的盖板

机架宽度: 4HP
材料: 铝
产品类型: 前面板
类型: 带把手的前面板 (PIU)
EMC 屏蔽: 是

技术参数

Table 1/2

物料号	机架高度	包装数量	手柄类型	安装	垫片类型	正面表面处理
20836-460	3U	1	IEL	正面螺钉安装	织物 EMC	阳极氧化
20836-461	6U	1	IEL	正面螺钉安装	织物 EMC	阳极氧化

Table 2/2

物料号	反面表面处理	符合	完成
20836-460	导电	PMC 夹层板, IEEE P1386	阳极氧化, 钝化

物料号	反面表面处理	符合	完成
20836-461	导电	PMC 夹层板，IEEE P1386	阳极氧化, 钝化

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE