


速卸锁扣

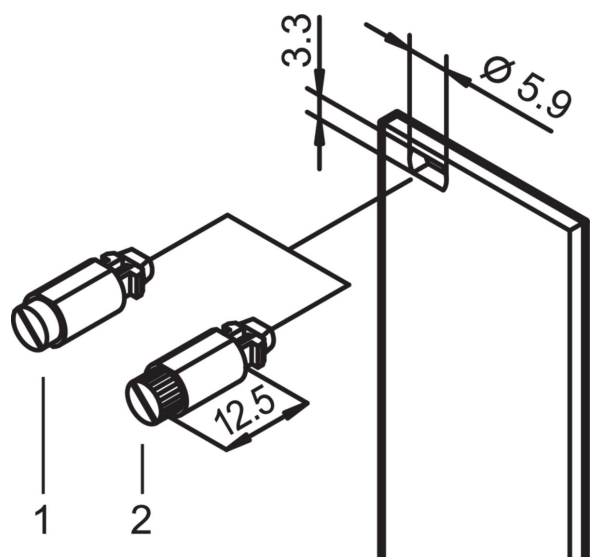

1/4 旋转锁，支持预定义的锁定位置。

功能

1/4 旋转锁，支持预定义的锁定位置

根据插槽位置识别锁定位置

抗振动，抗摇晃

数量 100 件

搭配：前面板
产品类型：硬件套件
完成：镀镍
材料：钢；锌合金；热塑性



技术参数

物料号	颜色	包装数量	颜色代码	深度	高度	宽度	紧固件类型
21101-850	墨黑色	100	RAL 9005	20.6mm	6mm	7mm	滚花，开槽头型
21101-847	卵石灰	100	RAL 7032	16.7mm	6mm	7mm	开槽头型
21101-849	卵石灰	100	RAL 7032	20.6mm	6mm	7mm	滚花，开槽头型
21101-848	墨黑色	100	RAL 9005	16.7mm	6mm	7mm	开槽头型

其他产品详情

速卸锁扣：无需螺纹插件即可安装。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE