


RatiopacPRO/-Air 配翻转式提手

用于 RatiopacPRO/-AIR 的折叠式把手，静态承载能力为 30 kg，无需机械工具即可改装仪器箱。

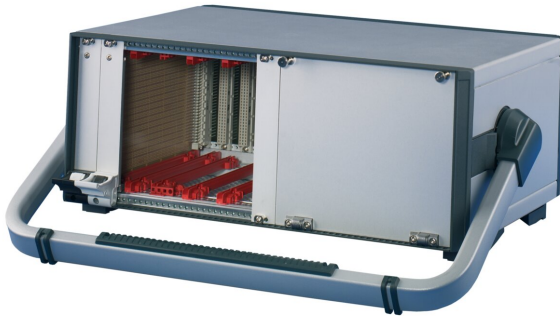

功能

可 30° 增量调节

无需机械工具即可改装仪器箱

静态承载能力 30 千克

对于桌面式应用，此把手有助于用户更方便地查看机箱正面

材料: 铝; ABS
 搭配: 仪器箱
 产品类型: 手柄
 产品系列: RatiopacPRO; RatiopacPRO AIR



技术参数

物料号	机架宽度	包装数量	手柄类型	颜色	完成
24571-320	42HP	1	翻转式把手	银色	粉末涂层
24571-322	84HP	1	翻转式把手	银色	粉末涂层
24571-321	63HP	1	翻转式把手	银色	粉末涂层

其他产品详情

不能与前把手一起使用。

翻转式把手需要装配套件，请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE