


# RatiopacPro 旋转把手装配套件

如果要安装折叠式把手，必须使用装配套件。应更换标准侧盖。

## 功能

铝侧面板，粉末涂层，RAL 9006, 转接卡和装配材料。

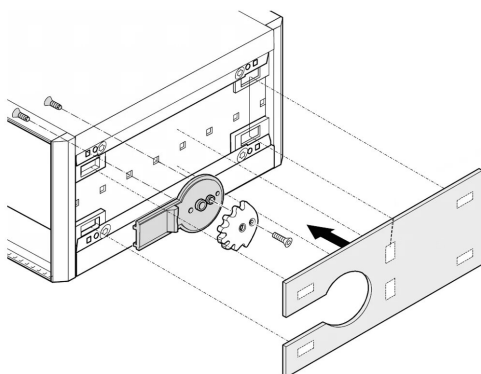

产品类型: 装配组件  
 搭配: 仪器箱  
 产品系列: RatiopacPRO; RatiopacPRO AIR  
 类型: 翻转式把手套装



## 技术参数

| 物料号       | 机架高度 | 机架宽度 | 深度    | 包装数量 | 完成   | 材料 |
|-----------|------|------|-------|------|------|----|
| 24571-354 | 3U   | 42HP | 375mm | 2    | 粉末涂层 | 铝  |
| 24571-363 | 4U   | 42HP | 495mm | 2    | 粉末涂层 | 铝  |
| 24571-352 | 3U   | 42HP | 255mm | 2    | 粉末涂层 | 铝  |
| 24571-355 | 3U   | 42HP | 435mm | 2    | 粉末涂层 | 铝  |
| 24571-362 | 4U   | 42HP | 435mm | 2    | 粉末涂层 | 铝  |
| 24571-356 | 3U   | 42HP | 495mm | 2    | 粉末涂层 | 铝  |
| 24571-361 | 4U   | 42HP | 375mm | 2    | 粉末涂层 | 铝  |
| 24571-359 | 4U   | 42HP | 255mm | 2    | 粉末涂层 | 铝  |
| 24571-353 | 3U   | 42HP | 315mm | 2    | 粉末涂层 | 铝  |

| 物料号       | 机架高度 | 机架宽度 | 深度    | 包装数量 | 完成   | 材料 |
|-----------|------|------|-------|------|------|----|
| 24571-360 | 4U   | 42HP | 315mm | 2    | 粉末涂层 | 铝  |

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE