


**适用于 RatiopacPRO/PropacPRO 的后面板，
通风孔，可加装电磁屏蔽功能**

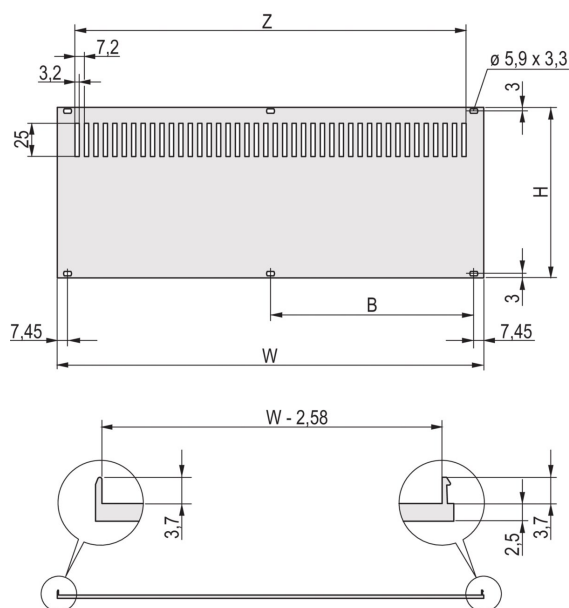

铝制 2.5 mm 网孔后面板为屏蔽型面板。背面具有导电性。

功能

背面板, 铝, 2.5 mm, 前部: 阳极氧化, 后部: 导电; 非屏蔽

可以安装在水平轨道上

材料:	铝
完成:	阳极氧化; 钝化
搭配:	仪器箱
产品系列:	RatiopacPRO; RatiopacPRO AIR
类型:	背板
产品类型:	侧面板



技术参数

物料号	机架高度	机架宽度	包装数量	高度	宽度
20848-744	5U	28HP	1	220mm	141.9mm
20848-656	4U	28HP	1	168.9mm	141.9mm
20848-659	4U	84HP	1	168.9mm	426.4mm
20848-658	4U	63HP	1	168.9mm	319.7mm
20848-679	2U	28HP	1	83.5mm	141.9mm
20848-643	6U	84HP	1	256mm	426.4mm

物料号	机架高度	机架宽度	包装数量	高度	宽度
20848-681	2U	63HP	1	83.5mm	319.7mm
20848-682	2U	84HP	1	83.5mm	426.4mm
20848-642	6U	63HP	1	256mm	319.7mm
20848-640	6U	28HP	1	256mm	141.9mm
20848-634	3U	42HP	1	123.4mm	213mm
20848-657	4U	42HP	1	168.9mm	213mm
20848-636	3U	84HP	1	123.4mm	426.4mm
20848-745	5U	42HP	1	220mm	213mm
20848-641	6U	42HP	1	256mm	213mm
20848-746	5U	63HP	1	220mm	319.7mm
20848-635	3U	63HP	1	123.4mm	319.7mm
20848-747	5U	84HP	1	220mm	426.4mm
20848-680	2U	42HP	1	83.5mm	213mm
20848-633	3U	28HP	1	123.4mm	141.9mm

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab Emirates
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE